




Montageanleitung B40 Hybridsteckverbinder

konfektionierbares Steckergehäuse mit Crimpanschluss, axial,
5x16mm² + 4xAWG22, ENP: Powerbuchse / Datenstift




Stückliste

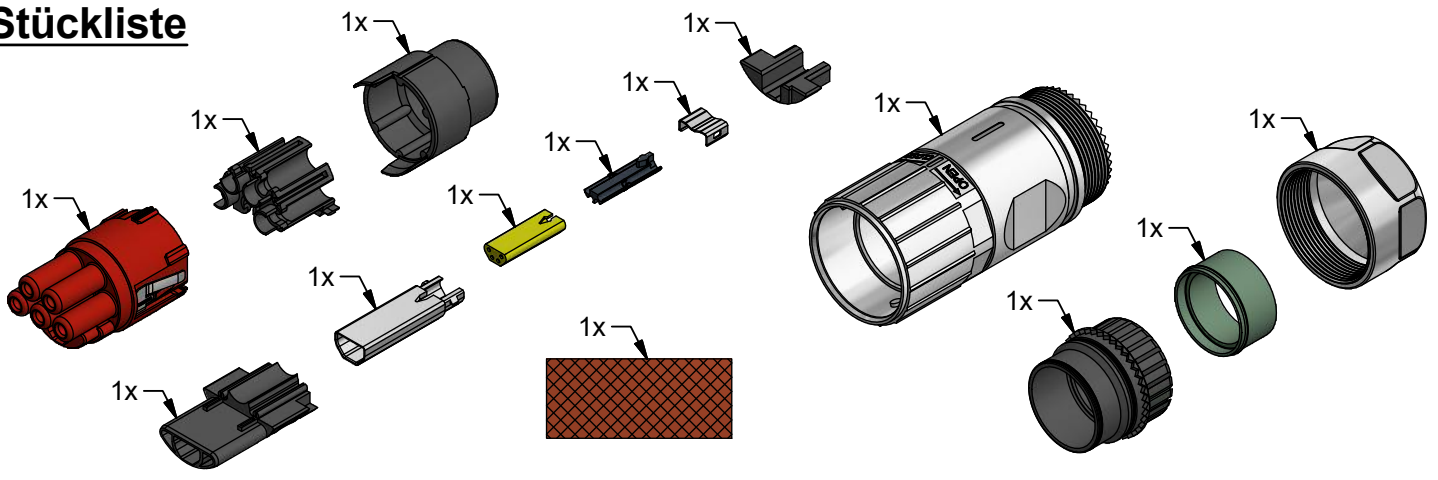

1 Einzelteile auf Leitung schieben

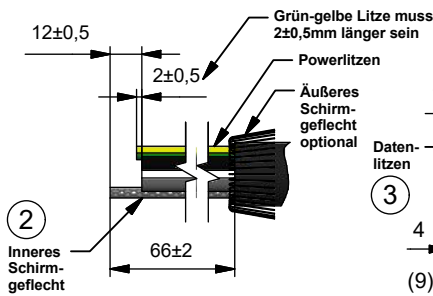
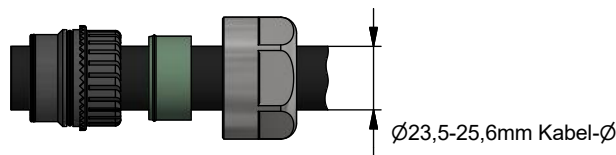


Füllstoffe bündig mit Kabelmantel wegschneiden!

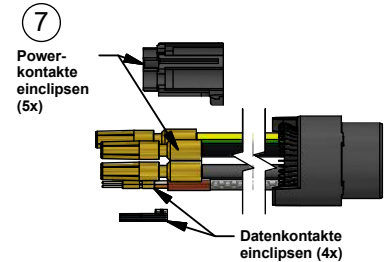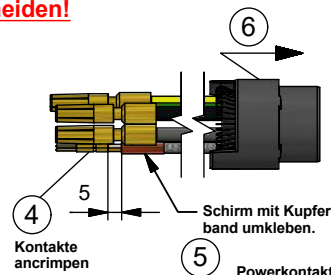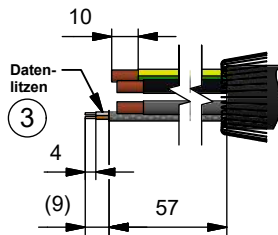

Powerkontakte:
Crimperät HC20 ohne Kopf - 6700 0100 1 (Art.-Nr. Fa. Rennsteig)
Crimpkopf 8.76-3 für HC20 - 6763 0000 6 (Art.-Nr. Fa. Rennsteig)
Locator ZB8810-0005 - 241109 (Art.-Nr. Fa. Beckhoff)
Einstellung für Crimpkopf - 3,30
Datenkontakte:
Crimpzange ZB8810-0000 - 159939 (Art.-Nr. Fa. Beckhoff)
Locator ZB8810-0001 - 159940 (Art.-Nr. Fa. Beckhoff)



Achtung: Ansicht von Kabelausgang dargestellt! Auf richtige Farbwahl achten!

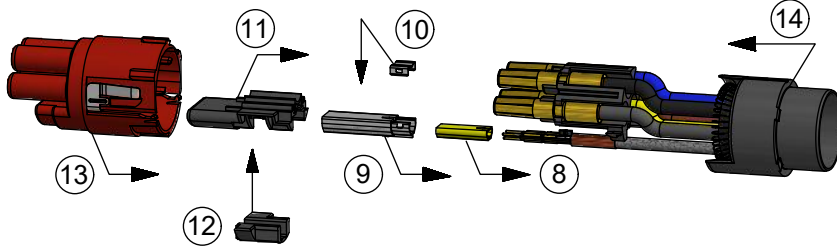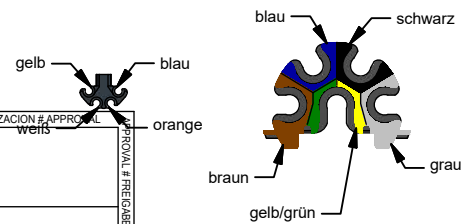

APPROVAL # FREIGABE # DEBLOCAGE # AUTORIZACION # APPROVAL	APPROVAL # FREIGABE # DEBLOCAGE # AUTORIZACION # APPROVAL
CUSTOMER APPROVAL DATE:	
NAME:	TITLE:
COMPANY NAME:	
APPROVAL # FREIGABE # DEBLOCAGE # AUTORIZACION # APPROVAL	APPROVAL # FREIGABE # DEBLOCAGE # AUTORIZACION # APPROVAL

Farbring optional
ZS7400-B006 (gelb)
ZS7400-B008 (grün)
ZS7400-B015 (orange)
ZS7400-B005 (rot)
ZS7400-B007 (blau)
ZS7400-B016 (grau)


Schirmgeflecht muss gekürzt werden und darf nicht über O-Ring ragen!

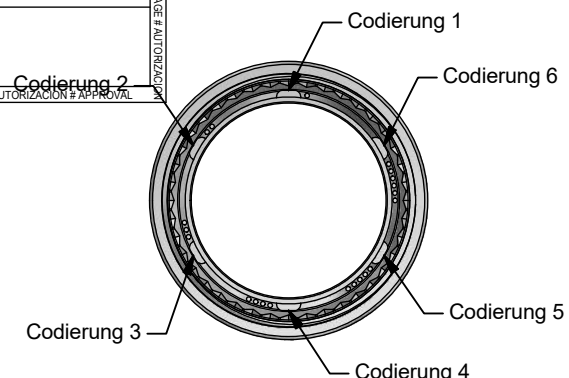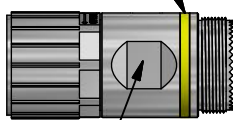



Assembly instruction B40 hybrid connectors

field attachable plug housing with crimp connection, axial,
5x16mm² + 4xAWG22, ENP: power (female) / data (male)



parts list

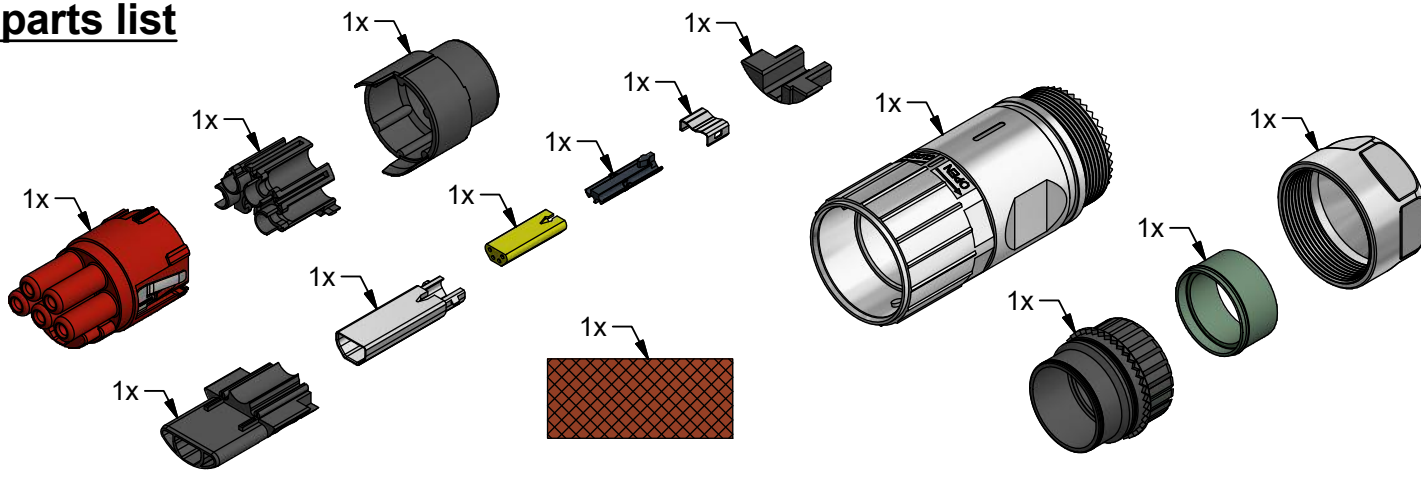

Please consider the cable direction!

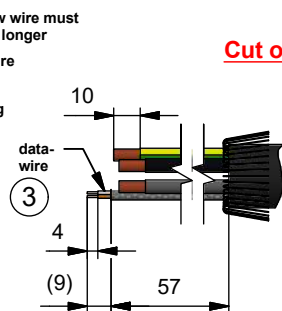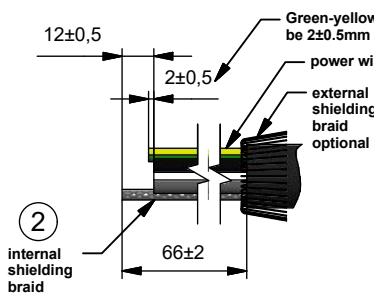


Cut off the fillers!

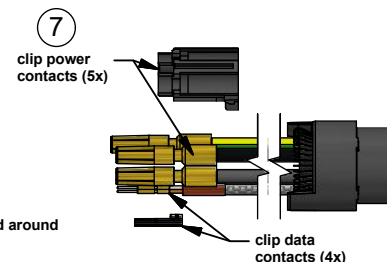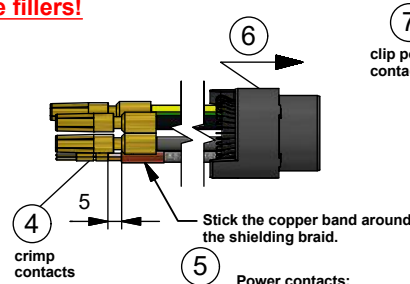


Power contacts:
Crimping tool HC20 without head - 6700 0100 1 (Rennsteig part-no.)
Crimping head 8.76-3 for HC20 - 6763 0000 6 (Rennsteig part-no.)
Locator ZB8810-0005 - 241109 (Beckhoff part-no.)
Adjustment for crimping head - 3,30

Data contacts:
Crimping tool ZB8810-0000 - 159939 (Beckhoff part-no.)
Locator ZB8810-0001 - 159940 (Beckhoff part-no.)

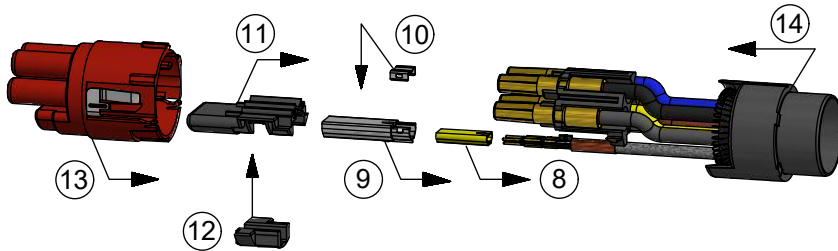

Attention: View from cable outlet!
Consider the right choice of colors!

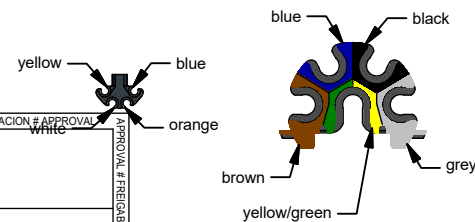

Farbring optional
ZS7400-B006 (yellow)
ZS7400-B008 (green)
ZS7400-B015 (orange)
ZS7400-B005 (red)
ZS7400-B007 (blue)
ZS7400-B016 (grey)

Shielding braid has to be shortened. It isn't allowed to protrude above the o-ring.
width across flats 41

