


# ZB8530 | U-clamp terminal up to 4 mm<sup>2</sup> for PE connection to the rail (10 x 3 mm)

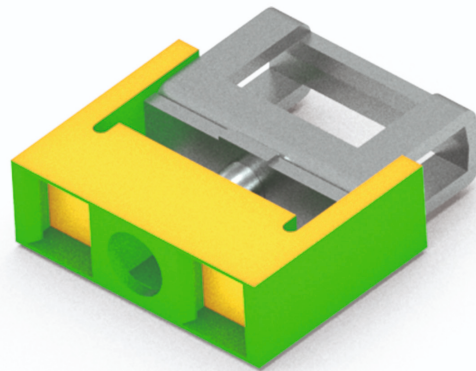

Mechanical data	
Accessories type	U-clamp terminal
Contact carrier color	green/yellow
Contact material	Steel
Max. wire cross-section	AWG26...AWG10 (0.14 mm <sup>2</sup> ...6 mm <sup>2</sup> ) according to CSA; AWG20...AWG12 (0.5 mm <sup>2</sup> ...4 mm <sup>2</sup> ) according to UL
Environmental data	
Special features	16 x 6 mm busbar connection
Approvals	CSA, CURUSEX, DEMKOATEX, GOSTME25, UR

## Notes

- Illustrations similar

Ordering information	
ZB8530	U-clamp terminal up to 4 mm <sup>2</sup> for PE connection to the rail (10 x 3 mm), packaging unit = 20 pieces



Products marked with a crossed-out wheeled bin shall not be discarded with the normal waste stream. The device is considered as waste electrical and electronic equipment. The national regulations for the disposal of waste electrical and electronic equipment must be observed.

Beckhoff®, TwinCAT®, TwinCAT/BSD®, TC/BSD®, EtherCAT®, EtherCAT G®, EtherCAT G10®, EtherCAT P®, Safety over EtherCAT®, TwinSAFE®, XFC®, XTS® and XPlanar® are registered trademarks of and licensed by Beckhoff Automation GmbH. Other designations used in this publication may be trademarks whose use by third parties for their own purposes could violate the rights of the owners.

© Beckhoff Automation GmbH & Co. KG 04/2023

The information provided in this brochure contains merely general descriptions or characteristics of performance which in case of actual application do not always apply as described or which may change as a result of further development of the products. An obligation to provide the respective characteristics shall only exist if expressly agreed in the terms of contract.